


Licensing SINUMERIK, SINAMICS and SIMOTION

General information about Web License Manager (WLM)

Web License Manager (WLM)

Table of content

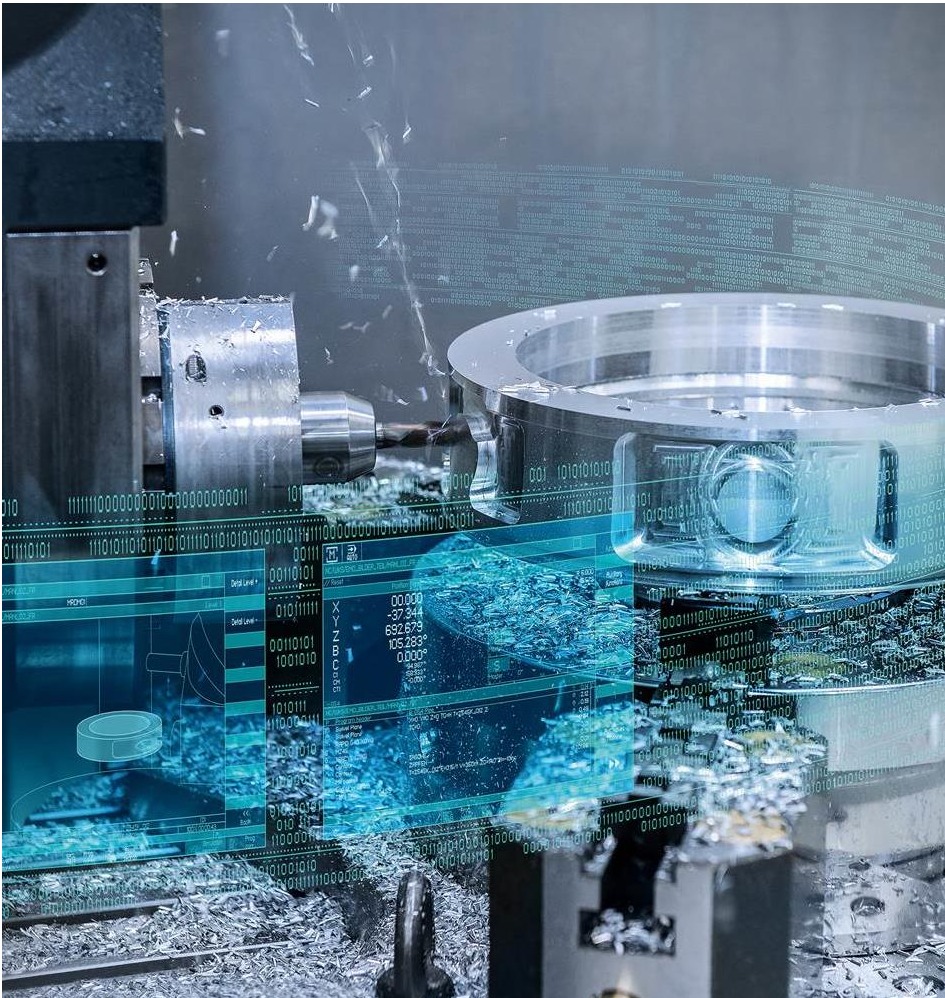

- Overview Web License Manager 3
- Licensing via **Direct Access** 6
- Licensing via **Barcode-/multiple assigning** 13
- Licensing via **Customer Login** 20
- Function **Manage License pool** 28
- Function **Display License Key** 37

Web License Manager enables machine tool builder licensing SINUMERIK, SINAMICS and SIMOTION

SINUMERIK

- NCK software options
- Mcenter software options
- Operate software options
- Compile cycles



SIMOTION

- Technology options (Motion Control, ...)
- Options for SIMOTION OA packages
- Options for SINAMICS integrated



SINAMICS

- Performance options
- Safety options
- Technology extensions



Consistent licensing in Web License Manager

Web License Manager is a web based application with three different licensing methods for different customer use cases

SIEMENS Chinese Deutsch Login

Web License Manager - INTERNET

User menu Contact

User menu

- › Direct access
- › Barcode-/multiple assigning
- › Customer login
- › Display license key
- › Manage license pool

Home

Update to the Web License Manager 3.0

You can learn more about the Web License Manager 3.0 here:

- [SINUMERIK_Licensing_direct_access.pdf](#)
- [EN_SINAMICS_RT_licenses_and_Web_License_Manager.pdf](#)
- [DE_SINAMICS_RT_Lizenzen_und_Web_License_Manager.pdf](#)

Welcome to the Web License Manager of Siemens DI MC!

The Web License Manager allows you to assign your software licenses online to a target system. You can assign several licenses at the same time. You will obtain a license key which you must transfer to your target system.

Before you can assign your software licenses, you must register using one of the following options:


- 1) **Direct access** allows you to assign all licenses which are included in the delivery.
- 2) **Barcode-/multiple assigning** has been optimized for operating a barcode scanner or licenses from different delivery notes.
- 3) **Customer login**, with an SiePortal account all licenses obtained so far can be assigned without CoL itself.

Web License Manager offers different variants for usage depending on customer requirements

Customer orders...


CoL's machine-specific

- Necessary licenses are bundled per delivery note

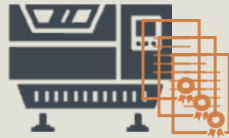

CoL's on paper - stock

- Necessary licenses are stock items, real as paper

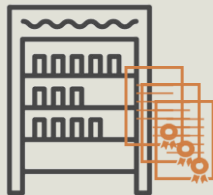

CoL's – „digital“ stock in WLM

- Necessary licenses are bundled per delivery note or stock item



Login / Licensing in Web License Manager

Direct access

- Assignment of licenses of a delivery note in one step
- Direct link from OSD possible

Multiple barcode assignment

- Assignment of licenses across delivery notes
- Capture of license data with barcode scanner

Customer Login *)

- Use of SiePortal access
- Filtering by delivery note possible
- All available licenses selectable WLM

Licensing via „Direct access“


see also in Siemens Online Support

<https://support.industry.siemens.com/cs/ww/de/view/109782608>


<https://support.industry.siemens.com/cs/ww/en/view/109782608>

Licensing process via Web License Manager – Direct access


Customer has (electronic) CoL available

 PDF

SIEMENS



SIMOTION
Technology option MultiAxes Package



Type of software / Software type: Runtime Software
Type of License / Lizenztyp: Single License
TYPE OF USE / Art der Nutzung: Installation
No. / Anzahl: 1
Software Class / Softwareklasse: A
Reference hardware / Zielhardware:
Serial Number of Hardware / Hardware-Seriennummer:
Remark / Anmerkung:
V00.00.04.00
Order No. / Bestell-Nr.: 6AU1820-0AA20-0A80
License No. / Lizenz-Nr.:
Dispatch note No. / Lieferschein-Nr.:

CERTIFICATE OF LICENSE

Please keep this document carefully filed.

This certificate with registered license is verification for you that the use of the software mentioned below is licensed by Siemens. The license number is necessary for ordering additional product-specific services.

Das Zertifikat bitte sorgfältig aufbewahren.

Dieses Zertifikat mit eingetragener Lizenznummer ist für Sie der Nachweis, dass die Nutzung unten genannter Software von Siemens lizenziert ist. Die Lizenznummer ist erforderlich zum Bezug von produkt spezifischen Zusatzleistungen.

Veuillez conserver soigneusement ce certificat.

Ce certificat portant le numéro de licence/licence number prouve que l'utilisation du logiciel mentionné ci-dessous fait l'objet d'une licence accordée par Siemens. Le numéro de licence/licence number est nécessaire pour acquies des prestations supplémentaires concernant le produit.

Si prega di conservare il certificato.

Questo certificato con il numero di licenza/licence number attesta che avete ricevuto l'uso del software sottostante da Siemens in licenza. Il numero di licenza/licence number è necessario per l'acquisto di integrazioni specifiche di prodotto.

Si prece guardarlo cuidadosamente.

Este certificado, con el número de licencia/licence number, es el comprobante para Usted de que tiene licencia de Siemens para utilizar el software mencionado abajo. El número de licencia/licence number es necesario para el pedido de prestaciones adicionales específicas del producto.

此是保單或證書。

此是保單或證書，證明您已獲得 Siemens 的許可，可合法使用以下所列之軟體。此證是申請產品附加服務時，必須提供該證。


Precondition for Direct access

- Everyone can use it without additional registration
- Electronic CoL or paper CoL is available
- Hardware serial number is available

Start Web License Manager (WLM)

<https://www.siemens.com/automation/license>

Unrestricted | © Siemens 2024 | DI MC | [siemens.com/automation/license](https://www.siemens.com/automation/license)



Licensing process via Web License Manager

1) Start WLM and generate License Key

WLM <https://www.siemens.com/automation/license>

use "Direct access"

automatic takeover of license data from OSD
Or
enter license number & delivery note number

Start License Key Generation

Next

License number:

Number of delivery notes:

Next

License certificate details:
SINUMERIK B40D
NCU-Systemsoftware 12 Axes
8 MB PCMCIA-Card; Standard
Type of Software / Softwareopt.: Runtime Software
Type of License / Lizenzierungsart: Standard
Type of User / Art der Nutzung: Installation
No. / Anzahl: 1
Software Class / Softwareklasse: A
Reference Software / Referenzsoftware:
Network / Antriebsweg

License No.: 10262000
Delivery note No. / Lieferchein-Nr.: 2443405

Licensing process via Web License Manager

2) Identify product

WLM

The image displays two screenshots of the Siemens Web License Manager (WLM) interface during the 'Identify product' step. The left screenshot shows the 'Identify product' step with callouts for selecting a product, entering a hardware serial number, and uploading a file. The right screenshot shows the 'Overview of all licenses' step with a callout for memory card assignment.

Select product

Enter hardware serial number manually or ...

... alternatively, it is possible to upload a .txt or .alm file. During license process web license manager work with the data from the file (hardware serial no.)

Overview of all licenses, which are already assigned to memory card

Licensing process via Web License Manager

3) Select licenses

WLM

SIEMENS

Web License Manager -

User menu Contact

User menu

- > Direct access
- > Barcode-/multiple assigning
- > Customer login
- > Display license key
- > Manage license pool

Direct a

Login Identify product **Select licenses** Assign licenses Genera key

Select the licenses you want to assign.

Product name: SINUMERIK ONE

Seriennummer der Hardware

Machine identifier: myMachineTool

Current license key

Product	Quantity	Max quantity	Box	License number
Additional 1 axis/spindle 6FC5800-0BA00-0Yx0	1	31	0	T-M T-M T-M
Additional 1 operation mode 6FC5800-0BC00-0Yx0	1	10	0	
channel	0	10	0	T-M

1) Define a machine identifier *) if needed (optional)

2) Select the necessary licenses

Hardware serial no. was entered manually or via file upload

- All licenses from the delivery note are displayed.
- Licenses that are already licensed will be displayed, even if they are not on the delivery note

Already licensed on the hardware

Licensing process via Web License Manager

4) Assign licenses

WLM

SIEMENS

Web License Manager -

User menu Contact -> Internal

User menu

- > Direct access
- > Barcode-/multiple assigning
- > Customer login
- > Display license key
- > Manage license pool

Direct access

Login Identify product Select licenses **Assign licenses** Generate license key

You would like to assign the following licenses to the product. If you continue, these licenses will be assigned. This operation cannot be undone by the user alone!

Product	License No.
CNC-SW 31-3 (from SW 6.0)	T-
6FC5852-1Xxxx-xYx0	

CSV export

Assign

Overview of all selected options / licenses

With "Assign" selected licenses were assign to the specified hardware (e.g. SD card)

© Siemens AG 2011 - 2019 Corporate Information | Privacy Policy | Terms of

Licensing process via Web License Manager

5) Generate license key

WLM

SIEMENS

Web License Manager -

User menu Contact -> Internal

User menu

- > Direct access
- > Barcode-/multiple assigning
- > Customer login
- > Display license key
- > Manage license pool

Direct access

Login Identify product Assign licenses Assign licenses **Generate license key**

A license key has been generated on the basis of licenses that you have assigned to a product.

Enter the license key on your target system.

The license key can be stored in a file:

- Download licensekey in ZIP file LK [redacted].zip
- Save the license report in PDF format

Next step: Register your Siemens products

The following licenses are assigned to the product SINUMERIK ONE with the Hardware serial number 1 [redacted] and sl [redacted]:

Assignment date ↑	Order number	Product	License number
24.03.2023	6FC5852-1Yxxx-xYx0	CNC-SW 31-3 (from SW 6.0)	T-[redacted]
30.06.2023	6FC5800-0BA00-0Yx0	Additional 1 axis/spindle	T-[redacted]

CSV export

Save license key on an USB-stick or network storage


Create a License report for documentation


Switch to MyRegistration Webpage

- Generated license key is now available, it contains all licenses assigned to memory card
- SINUMERIK ONE / SINUMERIK MC / SINAMICS S2x0
 - Save key at .zip file
- SINUMERIK 840D sl / SINUMERIK 828D
 - Save key at .alm file or
 - Save key at .txt file
- SINAMICS
 - Save key at keys.txt file
- Key activation is described in the system user manual.

Licensing via „Barcode-/multiple assigning“

Licensing process via Web License Manager – Barcode assigning Customer has (electronic) CoL available

 PDF



SIEMENS

SIMOTION
Technology option MultiAxes Package

Order No. / Bestell-Nr.: 6AU1820-0AA20-0A80
License No. / Lizenz-Nr.:
Dispatch note No. / Lieferschein-Nr.:

Type of software / Software type: Runtime Software
Type of License / Lizenztyp: Single License
TYPE OF USE / Art der Nutzung: Installation
No. / Anzahl: 1
Software Class / Softwareklasse: A
Reference hardware / Zielhardware:
Serial Number of Hardware / Hardware-Seriennummer:
Remark / Anmerkung:
V00.00.04.00

Order No. / Bestell-Nr.: 6AU1820-0AA20-0A80
License No. / Lizenz-Nr.:
Dispatch note No. / Lieferschein-Nr.:

CERTIFICATE OF LICENSE

Please keep this document carefully filed.
This certificate with registered license is verification for you that the use of the software mentioned below is licensed by Siemens. The license number is necessary for ordering additional product-specific services.

Si prega di conservare il certificato.
Questo certificato con numero di licenzia/certificate number attesta che avete ricevuto l'uso del software sottostante da Siemens in licenza. Il numero di licenzia/certificate number è necessario per l'acquisto di integrazioni specifiche di prodotto.

Das Zertifikat bitte sorgfältig aufbewahren.
Dieses Zertifikat mit eingetragenem Lizenznummer ist für Sie der Nachweis, dass die Nutzung unten genannter Software von Siemens lizenziert ist. Die Lizenznummer ist erforderlich zum Bezug von produktpezifischen Zusatzleistungen.

Silvase guardarlo cuidadosamente.
Este certificado, con el número de licenzia/certificate number, es el comprobante para Usted de que tiene licencia de Siemens para utilizar el software mencionado abajo. El número de licenzia/certificate number es necesario para el pedido de prestaciones adicionales específicas del producto.

Veuillez conserver soigneusement ce certificat.
Ce certificat portant le numéro de licenzia/certificate number prouve que l'utilisation du logiciel mentionné ci-dessous fait l'objet d'une licence accordée par Siemens. Le numéro de licenzia/certificate number est nécessaire pour acquiescer des prestations supplémentaires concernant le produit.

此证书应妥善保管。
此证书证明了您对以下所列软件的使用获得了西门子的许可。许可证号对于订购产品特定的附加服务是必需的。

此证书应妥善保管。
此证书证明了您对以下所列软件的使用获得了西门子的许可。许可证号对于订购产品特定的附加服务是必需的。

Precondition for Barcode-/multiple assigning

- Everyone can use it without additional registration
- Electronic CoL or paper CoL is available
- Hardware serial number and delivery note no. of memory card is available

Start Web License Manager (WLM)

<https://www.siemens.com/automation/license>

Licensing process via Web License Manager

1) Start WLM and identify hardware serial number

WLM <https://www.siemens.com/automation/license>

Use "Barcode-/multiple assigning"

Select your product e.g. SINUMERIK ONE & enter hardware serial number of memory card and delivery note number

Start License Key Generation

SIEMENS Web License Manager - INTERNET

User menu Contact

User menu

- > Direct access
- > **Barcode-/multiple assigning**
- > Customer login
- > Display license key
- > Manage license pool

Home

Update to the Web License Manager 3.0

You can learn more about the Web License Manager 3.0 here:

- SINUMERIK Licensing_direct_access.pdf
- EN SINAMICS RT licenses and Web License Manager.pdf
- DE SINAMICS RT Lizenzen und Web License Manager.pdf

Welcome to the Web License Manager of Siemens DI MC!

The Web License Manager allows you to assign your software licenses online to a target system.

Before you can assign your software licenses, you must register using one of the following options:

- Direct access:** This access allows you to assign all licenses.
- Barcode-/multiple assigning:** This access has been optimized for the assignment of licenses to a target system.
- Customer login:** If you have a personal access, you can...

Direct access with barcode

Identify product Enter licenses Assign licenses

Select the product you want to license. The serial number of the hardware and the delivery note number are printed on the memory card, alternatively the data is contained in the Data Matrix code. Note: Delivery note number is included in the Data Matrix code from production date 07-2023.

Product

Hardware serial number

Number of delivery note

Next

SIEMENS SINUMERIK ONE
6FC5851-1XG44-7YA0
SINUMERIK 840D sl
CNC-SW 31-3
SW 4.7 SP7 HF5 with CNC license
6 lng (en,ge,fr,it,sp,chs)
HW Ser. No.
Ser. No.
23.01.2020
04.07.07.05
Disp. Note No.

SIEMENS SINUMERIK ONE
6FC5852-1XG14-0YA0
CNC-SW 614 HP3
06.14.00.03
SW-Nr.:
HW-Nr.:

Hardware serial number

Number of delivery note

For the SINUMERIK product, you have also the possibility to determine the serial number of the hardware from a file:
Path to the keys.txt respectively *.alm file

File Datei auswählen Keine Datei ausgewählt

Licensing process via Web License Manager

2) Information about memory card

WLM

SIEMENS

Web License Manager - INTERNET

User menu Contact

User menu

- > Direct access
- > Barcode-multiple assigning
- > Customer login
- > Display license key
- > Manage license pool

Direct access with barcode

Identify product Enter

The licenses stated below have been assigned to the hardware.
Product name: SINUMERIK ONE
Hardware serial number: [blurred]
Machine identifier: [blurred]

List of already assigned licenses to memory card

Assignment date ↑	Product	Order number	Licenses
23.02.2021	Additional 1 operation mode modul (BAG)	6FC5800-0BC00-0Yx0	[blurred]
23.02.2021	Setpoint exchange	6FC5800-0BM05-0Yx0	[blurred]
23.02.2021	contour handiheel	6FC5800-0BM08-0Yx0	[blurred]
23.02.2021	Generic Coupling 'CP-EXPERT'	6FC5800-0BM74-0Yx0	[blurred]
23.02.2021	Run MyScreens	6FC5800-0BP64-0Yx0	[blurred]
23.02.2021	Inclined axis	6FC5800-0BM28-0Yx0	[blurred]
23.02.2021	Additional 1 machining channel	6FC5800-0BC10-0Yx0	[blurred]
23.02.2021	Travel to a fixed stop with force control	6FC5800-0BM01-0Yx0	[blurred]
23.02.2021	Multiple-axis interpolation (more than 4 axes)	6FC5800-0BM15-0Yx0	[blurred]
23.02.2021	TRANSMIT and peripheral surface transformation	6FC5800-0BM27-0Yx0	[blurred]
23.02.2021	Synchronized action stage 2	6FC5800-0BM36-0Yx0	[blurred]
23.02.2021	Angular head adapter	6FC5800-0BM56-0Yx0	[blurred]
23.02.2021	Tool management, more than 4 magazine	6FC5800-0BM88-0Yx0	[blurred]
23.02.2021	Add. HMI user memory on memory-Card NCU	6FC5800-0BP12-0Yx0	[blurred]
23.02.2021	Measurement of machine kinematic	6FC5800-0BP18-0Yx0	[blurred]

1 - 15 Next

Next

Licensing process via Web License Manager

3) Scan all necessary licenses for the machine

WLM

1) Define a machine identifier *) if needed

2) Scan license number AND Scan delivery note number from each CoL

3) Add license to list

Delivery note number

License number

Licensing process via Web License Manager

4) Assign licenses

WLM

SIEMENS

Web License Manager - INTERNET

User menu Contact

User menu

- > Direct access
- > **Barcode-/multiple assigning**
- > Customer login
- > Display license key
- > Manage license pool

Direct access with barcode

Identify product Enter licenses **Assign licenses** License Key generieren

The licenses stated below have been assigned to the hardware.

Product name: SINUMERIK 840D sl

Hardware serial number: [REDACTED]

Machine identifier: My_MKZ

PRODUCT	LIZENZNO
Additional 1 axis/spindle 6FC5800-0AA00-0Yx0	T-LO15X6667

CSV export

Assign

Overview of all selected options / licenses

With "Assign" selected licenses were assign to the specified hardware (e.g. SD card)

Licensing process via Web License Manager

5) Generate license key

WLM

SIEMENS Chinese Deutsch Login

Web License Manager -

User menu Contact -> Internal

User menu

- > Direct access
- > **Barcode-/multiple assigning**
- > Customer login
- > Display license key
- > Manage license pool

Direct access with barcode

Identify Enter licenses Ass

A license key has been generated on the basis of all licenses that you have assigned to the product.

The name of the license key is:

Enter the license key on your target system.

The license key can be stored in a file:

- Save the license key in SIN+...ay.alm
- Save the license key in keys.txt
- Save the license report in PDF format

Next step: Register your Siemens products

The following licenses are assigned to the product SINUMERIK 840D sl with the Hardware serial number ... and show the machine code

Assignment date ↑	Order number	Product	Licenses
14.01.2022	6FC5851-1Xxxx-xYx0	CNC-SW 31-3 (from SW 4.4)	T-...
30.06.2023	6FC5800-0AA00-0Yx0	Additional 1 axis/spindle	T-...
30.06.2023	6FC5800-0AC70-0Yx0	SI axis/spindle, add. 1 axis/spindle	T-...

CSV export

1 - 3

Generated license key

Save license key on a USB-stick or network storage

Create a License report for documentation


Switch to MyRegistration Webpage


- Generated license key is now available, it contains all licenses assigned to memory card
- SINUMERIK ONE / SINUMERIK MC / SINAMICS S2x0
 - Save key at .zip file
- SINUMERIK 840D sl / SINUMERIK 828D
 - Save key at .alm file or
 - Save key at .txt file
- SINAMICS
 - Save key at keys.txt file
- Key activation is described in the system user manual.

Licensing via „Customer Login“

Licensing process via Web License Manager – Customer Login

Licensing without (electronic) CoL

 PDF



SIEMENS

SIMOTION
Technology option MultiAxes Package

QR code and barcode

Order No. / Bestell-Nr.: 6AU1820-0AA20-0A80
License No. / Lizenz-Nr.:
Dispatch note No. / Lieferschein-Nr.:

Type of software / Software type: Runtime Software
Type of License / Lizenztyp: Single License
TYPE OF USE / Art der Nutzung: Installation
No. / Anzahl: 1
Software Class / Softwareklasse: A
Reference hardware / Zielhardware:
Serial Number of Hardware / Hardware-Seriennummer:
Remark / Anmerkung:
V00.00.04.00

Order No. / Bestell-Nr.: 6AU1820-0AA20-0A80
License No. / Lizenz-Nr.:
Dispatch note No. / Lieferschein-Nr.:

CERTIFICATE OF LICENSE

Please keep this document carefully filed.
This certificate with registered license is verification for you that the use of the software mentioned below is licensed by Siemens. The license number is necessary for ordering additional product-specific services.

Si prega di conservare il certificato.
Questo certificato con numero di licenzia/certificate number, attesta che avete ricevuto l'uso del software sottostante da Siemens in licenza. Il numero di licenzia/certificate number è necessario per l'acquisto di integrazioni specifiche di prodotto.

Das Zertifikat bitte sorgfältig aufbewahren.
Dieses Zertifikat mit eingetragenem Lizenznummer ist für Sie der Nachweis, dass die Nutzung unten genannter Software von Siemens lizenziert ist. Die Lizenznummer ist erforderlich zum Bezug von produktpezifischen Zusatzleistungen.

Silvase guardarlo cuidadosamente.
Este certificado, con el número de licenzia/certificate number, es el comprobante para Usted de que tiene licencia de Siemens para utilizar el software mencionado abajo. El número de licenzia/certificate number es necesario para el pedido de prestaciones adicionales específicas del producto.

Veuillez conserver soigneusement ce certificat.
Ce certificat portant le numéro de licenzia/certificate number prouve que l'utilisation du logiciel mentionné ci-dessous fait l'objet d'une licence accordée par Siemens. Le numéro de licenzia/certificate number est nécessaire pour acquiescer des prestations supplémentaires concernant le produit.

此证书必须妥善保管。
此证书证明了您对以下所列软件的使用获得了西门子的许可。许可证号对于订购产品特定的附加服务是必需的。

此证书必须妥善保管。
此证书证明了您对以下所列软件的使用获得了西门子的许可。许可证号对于订购产品特定的附加服务是必需的。

Precondition for Customer Login

- SiePortal account *) is available (contact Siemens for details)
- Hardware serial number is available
- (electronic) CoL is **not necessary** for licensing process

Start Web License Manager (WLM)

<https://www.siemens.com/automation/license>

Licensing process via Web License Manager

1) Start WLM and login at OSD (Online Software Delivery)

WLM <https://www.siemens.com/automation/license>

The image displays two screenshots of the Siemens Web License Manager (WLM) interface. The left screenshot shows the WLM home page with a 'User menu' on the left. A yellow callout box points to the 'Customer login' option in the menu. The right screenshot shows the login page at Online Software Delivery (OSD). A yellow callout box points to the login fields and a 'Login' button, with text indicating that users should login with their SiePortal account.

Use "Customer Login"

Login at Online Software Delivery with the SiePortal account

Licensing process via Web License Manager

2) Identify hardware serial number

WLM

SIEMENS Web License Manager

User menu (MallUser) Chinese Deutsch Logout

1) Select your product e.g. SINUMERIK ONE AND enter hardware serial number manually

Role and Login user name

2) Start License Key Generation

Customer login

Progress bar: Login, Identify product, Select licenses, Assign licenses, Generate license key

Select the product you want to license.

Product

Enter the Hardware serial number to which you want to assign licenses.

Hardware serial number

Next

Alternatively, it is possible to upload a .txt or .alm file. During license process web license manager work with the data from the file (hardware serial no. and necessary licenses)

For the SINUMERIK product, you have also the possibility to determine the serial number of the hardware by uploading a file.

File Keine ausgewählt

Licensing process via Web License Manager

3) Select licenses – serial no. was entered manually

WLM

1) Define a machine identifier *) if needed (optional)

2) Filter by delivery note number and/or machine identifier (optional)

3) Select the necessary licenses **)

Already licensed on the hardware

Hardware serial no. was entered manually

- All available licenses from SiePortal account (= license pool) are displayed.
- Licenses which are already licensed are displayed.
- Filter licenses via delivery note number and / or machine identifier is possible

Licensing process via Web License Manager

3) Select licenses – serial no. was uploaded via .alm file

WLM

SIEMENS

Web License Manager -

User menu

User menu

- > Direct access
- > Barcode-/multiple assigning
- > Customer login
- > Display license key
- > Manage license pool

1) Define a machine identifier if needed (optional)

2) Filter by delivery note number and/or machine identifier (optional)

Check box is visible if hardware serial no. was upload via.alm file

Already licensed on the hardware

3) Licenses are selected automatically *)

Hardware serial no. was uploaded via file

- With active check box (Yes), all necessary licenses defined by the .alm file are displayed, also they are not at license pool.
- Necessary licenses will be selected automatically .
- Licenses which are already licensed are displayed.
- Filter licenses via delivery note number and / or machine identifier is possible
- With inactive check box (No), all available licenses from the license pool are displayed.

Product	Quantity	Max quantity	Box	License number
Additional 1 axis/spindle 6FC5800-0BA00-0Yx0	2	31	<input type="checkbox"/>	T-M T-M
TRANSMIT and peripheral surface transformation 6FC5800-0BM27-0Yx0	0	1	<input checked="" type="checkbox"/>	T-M
Machining ... than 4 axes)	0	1	<input type="checkbox"/>	
	1	1	<input type="checkbox"/>	

Licensing process via Web License Manager

4) Assign licenses

WLM

SIEMENS

Web License Manager - INTERNET

User menu Contact

User menu

- > Direct access
- > Barcode-/multiple assigning
- > Customer login
- > Display license key
- > Manage license pool

Customer

Login Identify product Select licenses **Assign licenses**

Product	License No.
Safety Integrated - axes/spindle 6FC5800-0BK00-0Yx0	[Barcode]
Safety Integrated /SI-Logic 6FC5800-0BS60-0Yx0	[Barcode]

CSV export

1 - 2

Do you require email receipt notification?

Email address [Input field]

Back Next

Overview of all selected options / licenses

Possibility sending an Email notification

Assigning selected licenses to specified hardware (e.g. SD card)

Hardware serial no. was uploaded via file

- Licenses which are necessary but not available in the license pool are also listed

Licensing process via Web License Manager

5) Generate license key

WLM

SIEMENS

Web License Manager -

User menu Contact -> Internal

User menu

- > Direct access
- > Barcode-/multiple assigning
- > **Customer login**
- > Display license key
- > Manage license pool

Customer login

Login Identify product Select licenses Assign licenses **Generate license key**

A license key has been generated on the basis of all licenses that you have assigned to the memory card.

Enter the license key on your target system:

The license key can be stored in a file:

- Download licensekey in ZIP file LK_...zip
- Save the license report in PDF format
- Download the license certificates of the memory card as a ZIP file - LC_...zip

Next step: [Register your Siemens products](#)

The following licenses are assigned to the product SINUMERIK ONE with the Seriennummer der Hardware ... and ...

1 - 3 of 3

Assignment date	Order number	Product	Licenses
14.12.2023 09:22	6FC5800-0BA00-0Yx0	Additional 1 axis/spindle	
14.12.2023 09:28	6FC5800-0BB00-0Yx0	Additional 1 positioning axis/auxiliary spindle	
09.01.2024 11:26	6FC5800-0BA00-0Yx0	Additional 1 axis/spindle	

1 - 3 of 3

- Generated license key is now available, it contains all licenses assigned to memory card
- SINUMERIK ONE / SINUMERIK MC / SINAMICS S2x0
 - Save key at .zip file
 - Save license certificates at .zip file
- SINUMERIK 840D sl / SINUMERIK 828D
 - Save key at .alm file or
 - Save key at .txt file
- SINAMICS
 - Save key at keys.txt file
- Key activation is described in the system user manual.

**Web License Manager –
Manage License pool**

**License pool is part of
Online Software Delivery (OSD)**

Web License Manager – Manage License Pool to get an overview in Online Software Delivery to all ordered licenses

OSD

Delivery Note No.	Dispatch date	Article Description	License No.	HW Serial No.	Machine Label
	02/24/2021	SINUMERIK ONE Access MyMachine /OPC UA - PLC		---	---
	02/24/2021	SINAMICS S Lizenz Performance 1		---	---
	02/24/2021	SINAMICS S Lizenz Performance 1		---	---
	02/24/2021	SINAMICS S Lizenz Performance 1		---	---
	02/24/2021	SINAMICS S Lizenz Performance 1		---	---
	02/24/2021	SINAMICS S Lizenz Performance 1		---	---
	02/09/2021	SINUMERIK ONE Access MyMachine /OPC UA - PLC		---	---

Precondition for Manage License pool

- SiePortal account *) is available (contact Siemens)
- Delivery note number

Benefit for the customer

- Get an overview of all obtained licenses
- Search-, export- and get more details about licenses
- Download electronic CoL's
- Select one license and start licensing with link to WLM

Start Web License Manager (WLM)

<https://www.siemens.com/automation/license>

Web License Manager – Manage License Pool

1) Start WLM and Login at OSD (Online Software Delivery)

WLM <https://www.siemens.com/automation/license>

The image displays two screenshots of the Siemens Web License Manager (WLM) interface. The left screenshot shows the WLM home page with a 'User menu' on the left side. A yellow callout box points to the 'Manage license pool' option in the user menu, with the text 'use "Manage license pool"'. The right screenshot shows the login page at Online Software Delivery (OSD). A yellow callout box points to the login fields, with the text 'Login at Online Software Delivery with the SiePortal account'. The OSD page includes fields for 'Login' and 'Password', a 'Login' button, and options for 'Login with Windows authentication' and 'Login with PKI'. A note at the bottom of the OSD page reads: 'Please note: Change passwords at regular intervals to raise the protection from data theft.'

Web License Manager – Manage License Pool

2) Login at Online Software Delivery and define your role

OSD

SIEMENS Online Software Delivery

Online Software Delivery ▶ Language ▶ Support ▶ Help

Your authentication has been successful! In Online Software Delivery there are multiple roles defined for your user name. Please select one of the following roles to sign up.

Role description:

- **Consignee:** Download of the ordered software and activation of corresponding license keys
- **Purchaser:** Contract management (change, cancel), viewing orders (no download possible)
- **Mall User:** Access to all orders and all contracts for the assigned customer number (download possible, change or cancel contract)

Your login name:

Swdl

Role	Factory	Region	Customer No.
> Consignee		-	
> Purchaser		-	

Online Software Delivery (OSD)

provides you with a comfortable way to get and manage your purchased License Keys.

Role description:

- **Consignee:** Download of the ordered software and activation of corresponding license keys
- **Purchaser:** Contract management (change, cancel), viewing orders (no download possible)
- **Mall User:** Access to all orders and all contracts for the assigned customer number (download possible, change or cancel contract)

Web License Manager – Manage License Pool

3) Use License Overview to manage purchased licenses

OSD

SIEMENS Online Software Delivery

Online Software Delivery | Language | Support | Help | Site Explorer

Product Download | **License Overview** | Contracts

Customer Data | Order Data | Product Data | Contract Data | Download Status | Customer Specific

Filter applied: available

Delivery Note No.	Dispatch date	Article Description	License No.	HW Serial No.	Machine Label	State	Serial No.	Download date	Downloader	EKB file	Customer order number
	02/24/2021	SINUMERIK ONE Access MyMachine /OPC UA - PLC			---						my BSTK D tigung
	02/24/2021	SINAMICS S Lizenz Performance 1									STKD gung
	02/24/2021	SINAMICS S Lizenz Performance 1			---						STKD gung
	02/24/2021	SINAMICS S Lizenz Performance 1			---						STKD gung
	02/24/2021	SINAMICS S Lizenz Performance 1			---						STKD gung
	02/24/2021	SINAMICS S Lizenz Performance 1			---						STKD gung
	02/24/2021	SINAMICS S Lizenz Performance 1			---						STKD gung
	02/09/2021	SINUMERIK ONE Access MyMachine /OPC UA - PLC			---						STKD tigung

Login name and role

License Overview show a list of all licenses belong to the customer number.
Many filters are available for search e.g. show all licenses not assigned yet

Web License Manager – Manage License Pool

3) Use License Overview to manage purchased licenses

OSD

Online Software Delivery

Online Software Delivery
▶ Language
▶ Support
▶ Help
▶ Site Explorer

Product Download
License Overview
Contracts

Customer Data ▼ | Order Data ▼ | Product Data ▼ | Contract Data ▼ | Download Status ▼ | Customer Specific ▼
chosen filter: Default filter Chosen view: Basic View

◀ < | 1 | 2 | 3 | 4 | 5 | 6 | 7 | 8 | 9 | 10 | ... | > ▶
Result per page

Delivery Note No.	Dispatch date	Article Description	License No.	HW Serial No.	Machine Label	State	Serial No.	Download date	Downloader	EKB file	Customer order number	End Customer Order No.	Article No.	Customer Specific 1	Customer Specific 2	Customer Specific 3	Customer Licence Key	Actions
	07/23/2021	SINUMERIK 840D SL SINUMERIK Operate/NCU			---	available	MC0000025853	---	---	---		---	6FC5800-0AS00-0YH0	---	---	---	---	
	07/23/2021	SINAMICS S120 Performance 1 SW 5.2 SP3 HF6			---	downloaded	MC0000025832	07/23/2021	Produktion	---		---	6SL3054-0FC31-1BA0	---	---	---	---	

Hardware serial no. of memory card the license is assigned to

available = license is unassigned yet
downloaded = license is already assigned

Date is only available in connection with WLM customer Login
Download date: date of assignment
Downloader: Login name

Customer can edit for customer specific information.

Web License Manager – Manage License Pool

4) Use Product Download to choose license and Go to WLM

OSD

Product Download show a list of all orders belong to the customer number.

Many filters are available for search e.g. show a specific order

electronic CoL download as PDF file

Direct link to Web License Manager

✔ means download is already done

- Use direct link “Go to WLM” to generate license key and licensing the runtime functionality.

Position	Article No., Description, Contract No.	Quantity	Certificate of License/Contract	License Key
	Delivery Note () from September 13, 2019 Cust. No.: A.....			Go to WLM
000001	6SW1700-5JD00-1AH0 Drive Engineering System Drive ES PCS7 1 Runtime license for EPL Royalty	1	PDF Certificate ✔	Go to WLM
	Delivery Note () from September 13, 2019 Cust. No.: A.....			Go to WLM
000001	6SW1700-5JD11-4 Drive Engineering System Drive ES PCS7 1 Runtime license for EPL Royalty	1	PDF Certificate ✔	Go to WLM
	Delivery Note () from August 20, 2019 Cust. No.: A.....			Go to WLM
000002	6FC5852-1XF00-0YB0 SINUMERIK ONE CNC-SW with SINUMERIK Operate 6 Ing. (en, de, fr, it, sp, chs)	1	PDF Certificate	Go to WLM

ECOL-6FC5800-0B....pdf

Web License Manager – Manage License Pool

OSD offers downloading the delivery note

OSD

SIEMENSOnline Software Delivery

Online Software Delivery▶ Language▶ Support▶ Help▶ Site Explorer

Product Download [License Overview](#) [Contract Manager](#)

Customer Data ▼ | Order Data ▼ | Product Data ▼ | Contract Data ▼ | Download State License ▼chosen filter: Default filter

Filter applied: x x [Reset all filters](#)« < | 1 | > » 10

Position	Article No., Description, Contract No.	Quantity	Certificate of License/Contract	License Key	Software-Files and Documents	Further Information
Delivery Note from June 27, 2023 Cust. No.: Region: NEW Certificate Go to WLM Download Packing List (PDF)						
000001	6FC5800-0BM27-0YB0 SINUMERIK ONE TRANSMIT and peripheral surface trans.	1	Certificate	Go to WLM	No downloads included	Details
000002	6FC5800-0BM30-0YB0 SINUMERIK ONE Machining package 5 axis	1	Certificate	Go to WLM	No downloads included	Details
000003	6FC5800-0BS16-0YB0 SINUMERIK ONE Spline interpolation	1	Certificate	Go to WLM	No downloads included	Details
000004	6FC5800-0BM74-0YB0 SINUMERIK ONE Generic Coupling CP-EXPERT	1	Certificate	Go to WLM	No downloads included	Details
000005	6FC5800-0BM48-0YB0 SINUMERIK ONE 3D Tool radius compensation	1	Certificate	Go to WLM	No downloads included	Details

Hint

- Use “**Downloading Packing List (PDF)**” function
- Delivery note is 12 month available
- Delivery note is downloadable from consignee and user with mail account.
- Download is available two days after delivery

Web License Manager – Manage License Pool

5) licensing in WLM with Direct access

The screenshot displays the Siemens Web License Manager (WLM) interface. At the top left, there is a 'WLM' tab. Below it, the 'SIEMENS' logo and 'Web License Manager - INTERNET' are visible. A navigation bar includes 'User menu' and 'Contact'. The 'User menu' is expanded, showing options: '> Direct access', '> Barcode-/multiple assigning', '> Customer login', '> Display license key', and '> Manage license pool'. A yellow callout box points to 'Direct access' with the text 'Direct access is selected'. Below the menu, a progress bar shows steps: 'Login', 'Identify product', 'Select licenses', 'Assign licenses', and 'Generate lic'. The 'Select licenses' step is active. The main content area contains the instruction: 'Please enter a license number that you want to assign, as well as the number of the associated delivery note. You will find this information on your Certificate of License, as shown below.' There are two input fields: 'License number' with the value '123456789' and 'Number of delivery note' with the value '009123456'. A yellow callout box points to these fields with the text 'License number and delivery note number is automatically taken from OSD'. Below the input fields is a 'Captcha' section with a purple image of '19DIP2' and an empty input box. A 'Next' button is at the bottom left.

After selecting the license in OSD licensing could be done at WLM.

Web License Manager – Display License Key

Web License Manager – Display License Key to create a license report afterwards or for service to check license key

WLM

Please keep this license report carefully filed.
For the license number entered and marked with "No" in the column "CoL delivered", this report shall provide you evidence that the use of the below-mentioned software at the time of creation of the report has been licensed by Siemens to the extent listed. Product-specific add-on services can be obtained stating the license number. This report does not apply to license numbers contained therein marked with "Yes" in the column "CoL delivered". The Certificate of License supplied with this software shall provide evidence of license instead.

Den Lizenzreport bitte sorgfältig aufbewahren.
Bei den eingetragenen Lizenznummern, die in der Spalte "CoL geliefert" mit "No" gekennzeichnet sind, gilt dieser Report für Sie als der Nachweis, dass die Nutzung unten genannter Software zum Zeitpunkt der Reporterstellung in dem aufgelisteten Umfang von Siemens lizenziert ist. Die Lizenznummer ist erforderlich zum Bezug von produkt-spezifischen Zusatzleistungen. Bei Lizenznummern, die in der Spalte "CoL geliefert" mit "Yes" gekennzeichnet sind, die aber auch in diesem Report aufgeführt sind, gilt nicht dieser Report, sondern das mit dieser Software ausgelieferte Certificate of License als Lizenzierungsnachweis.

SINUMERIK ONE

Siemens Digital Industries
Motion Control
Web License Manager



Date, Time / Datum, Uhrzeit: 25.02.2021 09:47:44
The following licenses are currently assigned to:
Product: SINUMERIK ONE

Serial number of hardware: [redacted]
Current License Key:
[redacted]
Machine Identifier:

license
REPORT

SIEMENS

Precondition for Manage License pool

- Hardware Serial number or license number

Benefit for the customer

- License report could be created for documentation
- Existing license key for a memory card can be shown
- Machine tool builder / Service can check which licenses are on the machine at end customer

Start Web License Manager (WLM)

<https://www.siemens.com/automation/license>

Web License Manager – Display License Key

1) Identify License key

WLM <https://www.siemens.com/automation/license>

The screenshot shows the 'Show License Key' page in the Siemens Web License Manager. The page title is 'Show License Key' and it includes a sub-header 'Web License Manager'. A 'User menu' is visible on the left with options like 'Direct access', 'Barcode-/multi-assigning', 'Customer login', 'Display license key' (highlighted), and 'Manage license pool'. The main content area has a heading 'Show License Key' and a description: 'This information function is used to display the license key'. Below this, it says 'Please fill in one of the three fields.' and lists three input fields: 'Hardware serial number', 'License no.', and 'Machine identifier'. There are 'Show License Key' and 'Reset' buttons. Below the input fields, the 'License Key' is displayed as a masked string. A section titled 'The license key can be stored in a file:' contains a link: 'Lizenzkey in ZIP-Datei LK_S4P9G8JD41A8YBY1.zip herunterladen'. At the bottom, there is a section 'Further, you can obtain a license report including a compilation of all assigned licenses.' with an 'Email address' input field and a 'Get license report' button. Three callouts provide instructions: 1) 'use "Display license key"' points to the menu item. 2) 'Enter Hardware serial number OR License number → Existing License key is shown' points to the input fields. 3) 'License key can be stored AND License report can be sent to an Email address' points to the download link and email input field.

use "Display license key"

Enter Hardware serial number
OR
License number
→ Existing License key is shown

License key can be stored
AND
License report can be sent
to an Email address

Web License Manager – Display License Key

2) License report

WLM

Please keep this license report carefully filed.
For the license number entered and marked with "No" in the column "CoL delivered", this report shall provide you evidence that the use of the below-mentioned software at the time of creation of the report has been licensed by Siemens to the extent listed. Product-specific add-on services can be obtained stating the license number. This report does not apply to license numbers contained therein marked with "Yes" in the column "CoL delivered". The Certificate of License supplied with this software shall provide evidence of license instead.

Den Lizenzreport bitte sorgfältig aufbewahren.
Bei den eingetragenen Lizenznummern, die in der Spalte "CoL geliefert" mit "No" gekennzeichnet sind, gilt dieser Report für Sie als der Nachweis, dass die Nutzung unten genannter Software zum Zeitpunkt der Reporterstellung in dem aufgelisteten Umfang von Siemens lizenziert ist. Die Lizenznummer ist erforderlich zum Bezug von produkt-spezifischen Zusatzleistungen. Bei Lizenznummern, die in der Spalte "CoL geliefert" mit "Yes" gekennzeichnet sind, die aber auch in diesem Report aufgeführt sind, gilt nicht dieser Report, sondern das mit dieser Software ausgelieferte Certificate of License als Lizenzierungsnachweis.

SINUMERIK ONE

Siemens Digital Industries
Motion Control
Web License Manager

Date, Time / Datum, Uhrzeit: 25.02.2021 09:47:44
The following licenses are currently assigned to:
Product: SINUMERIK ONE

Serial number of hardware: S4P9G6J041A8YBY1
Current License Key: CNZF-TA2X-AXBP-LTTB-CN2M-BBMS-QBFG-XAAV-DLTK-ECEL-KGB-ETSE-XDPT-KLVM-LETV-FM6K-FEF-I-XEWC-UMC
Date, Time / Datum, Uhrzeit: 25.02.2021 09:47:44

Machine Identifier: S4P9G6J041A8YBY1

Order No.	Product	License No.	CoL supplied
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X1149	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X2625	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X2883	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X2935	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X3210	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X3626	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X4262	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X4405	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X5254	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X7938	No
6FC5800-0BA00-0YX0	Additional 1 axis/spindle	T-M223X3485	No
6FC5800-0BB00-0YX0	Additional 1 positioning axis/auxiliary spindle	T-M223X3920	No
6FC5800-0BC00-0YX0	Additional 1 operation mode modul (BAG)	T-M223X3905	No

license REPORT

SIEMENS

license REPORT

SIEMENS

License report is for customer documentation

Information on the report:

- Serial number of hardware
- Current license key
- List of all assigned licenses of hardware

| Contact

Siemens AG

Digital Industries
Motion Control
License Team SINUMERIK

Frauenauracher Str. 80
91056 Erlangen, Germany

Subject to changes and errors. The information given in this document only contains general descriptions and/or performance features which may not always specifically reflect those described, or which may undergo modification in the course of further development of the products. The requested performance features are binding only when they are expressly agreed upon in the concluded contract.

All product designations, product names, etc. may contain trademarks or other rights of Siemens AG, its affiliated companies or third parties. Their unauthorized use may infringe the rights of the respective owner.